

# DATA CENTER SOLUTIONS

Everything you need in the new digital era, from the world leader in Energy and Digital Solutions

# PRYSMIAN CONNECTS AND IS CONNECTED

Prysmian is the world leader in the development and manufacture of power and telecommunication cables. Our portfolio provides the wrap-around cable infrastructure for data centre facilities.



**33,000** people

With experts ready for every project.



**50+** countries

We're uniquely placed to serve our customers, wherever they are.



**109** manufacturing plants

Ensuring we maintain some of the industry's shortest lead times.



**27** R&D&i centres

Innovation and excellence - across every aspect of our business.

# ALWAYS IN CONTROL OF THE PROCESS - DIGITAL SOLUTIONS OPERATIONS



**USA:**  
- Connectivity Manufacture  
- Singlemode Fibres  
- 16f Ribbon  
- FlexRibbon  
- MMC/16f



**UK:**  
- Connectivity Manufacture  
- Duplex/MPO Terminations



**France:**  
- Singlemode Fibres



**Netherlands:**  
- Multimode Fibres



**Romania:**  
- Interconnect Cable  
- Ribbon Cable



**Slovakia:**  
- Internal & MPO Cable  
- Category Cable  
- Pre-termination



**Spain:**  
- FO Cable manufacturing



**Portugal:**  
- Category Cables



**Germany:**  
- Category Cables



**China:**  
- Fibre Manufacture  
- Duplex/MPO Terminations



**Vietnam:**  
- Duplex/MPO Terminations  
- Cassette Manufacture

 


**Philippines:**  
- Duplex/MPO Terminations  
- Cassette Manufacture

# COMPLETE DATA CENTER OVERVIEW



**TELECOMS SOLUTIONS**

-  Long-haul interconnect (submarine and terrestrial) solution
-  Building interconnect solution
-  Indoor pre-connectorised solution

**ENERGY SOLUTIONS**

-  Energy connection to main grid (HV and MV)
-  Local energy distribution
-  Indoor energy distribution

UHD connectivity




Prysmian's UHD distribution solution



Pre-Connectorised UC Connect



Trunking solutions

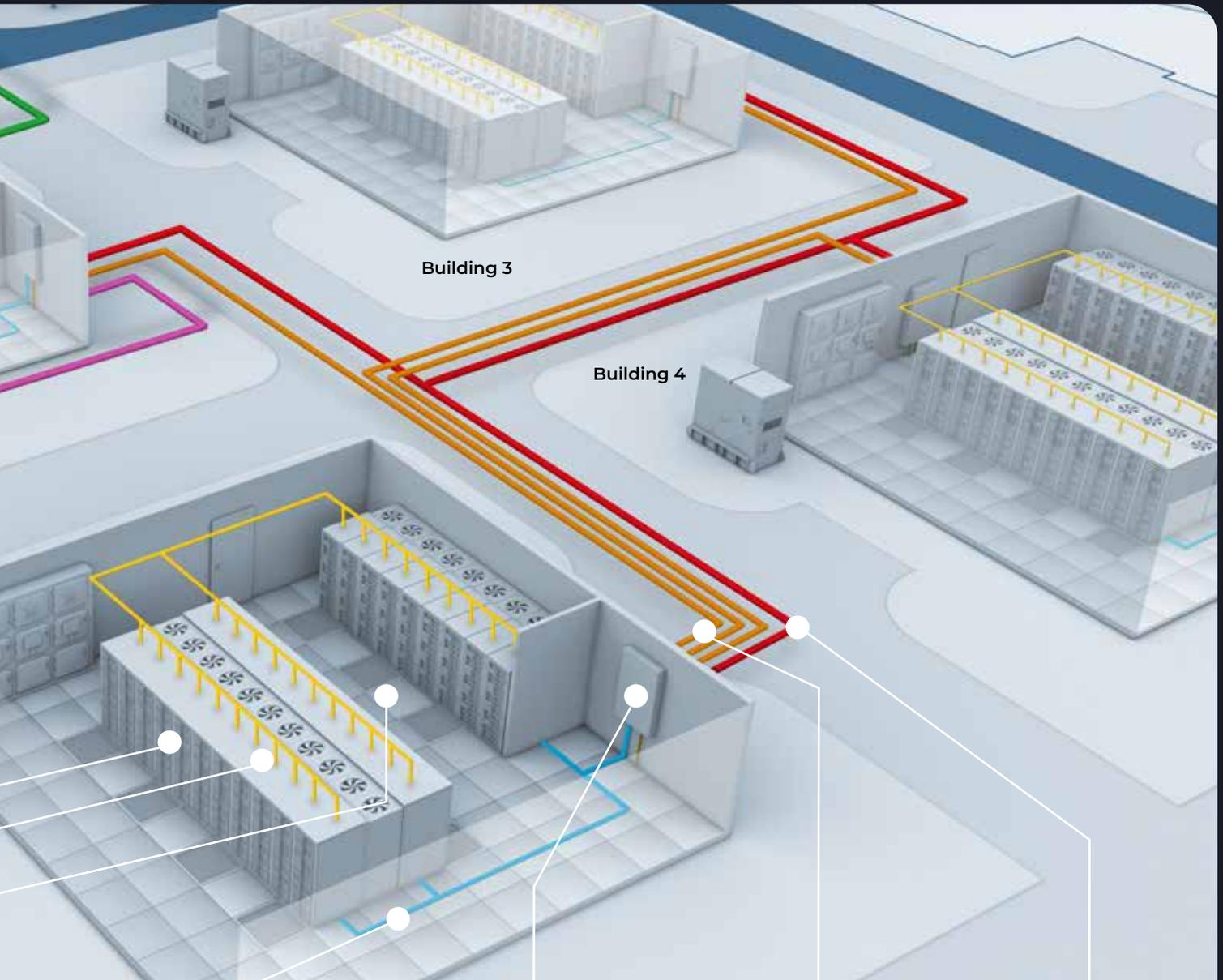

Prysmian Energy LV



Cable monitoring technology




FlexTube®  
FlexRibbon™  
Sirocco®  
Loose Tube 200µm




Prysmian Energy MV  
+ Prysmian Electronics

Interconnection Cables

# UC FIBRE

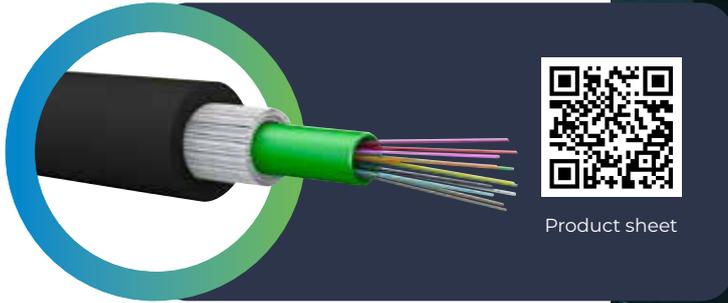

**Uni Tube**

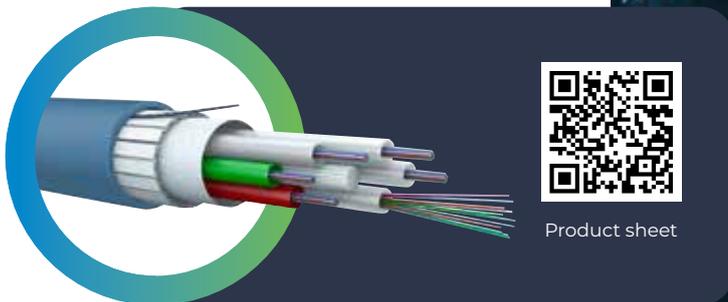

**Multi Loose Tube**



**Tight Buffered**

## COMPLETE PRODUCT RANGE

- Indoor/Outdoor
- Blown fibre
- Distribution/Breakout
- Steel wire armour and CST
- Cables for harsh environments
- Trunk and MPO patch cord assembly
- Fibre optic cables for data centres

## CPR COMPLIANCE

- Unique supplier of: non-metallic, gel-filled cables,  $C_{ca} + B2_{ca}$  approved, up to 288 fibres

## BENDBRIGHT XST™ FIBRE

- World-class bend-insensitive fibre
- Including OM5 and OS2

# ADVANCED HIGH DENSITY CABLE SYSTEMS FOR DATA CENTERS INTERCONNECTIONS




## FlexTube®

- Up to 1 728 fibres.
- Easy to access the fibers (end access) / easy to install tubes.



## FlexRibbon™

- Up to 6 912 fibres.
- Mass splicing.
- Highest fibre count.

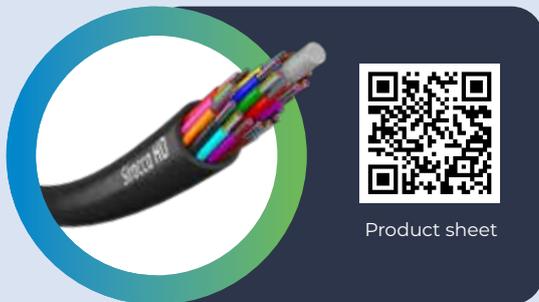

## Sirocco®



- Up to 864 fibres in 11.5 mm.
- Smallest cable size / sustainability.
- After optimisation of the optical fibre and materials and rigorous testing, Prysmian Sirocco cables now have an expected lifetime of 50+ years without compromise on performance during that time. This enables operators to calculate the lifecycle analysis of their network over a much longer period of time.



## Loose tube 200µm

- Smaller diameter and weight than standard loose tube cables (20% reduction in diameter).

# INTERNAL DATA CENTER PORTFOLIO

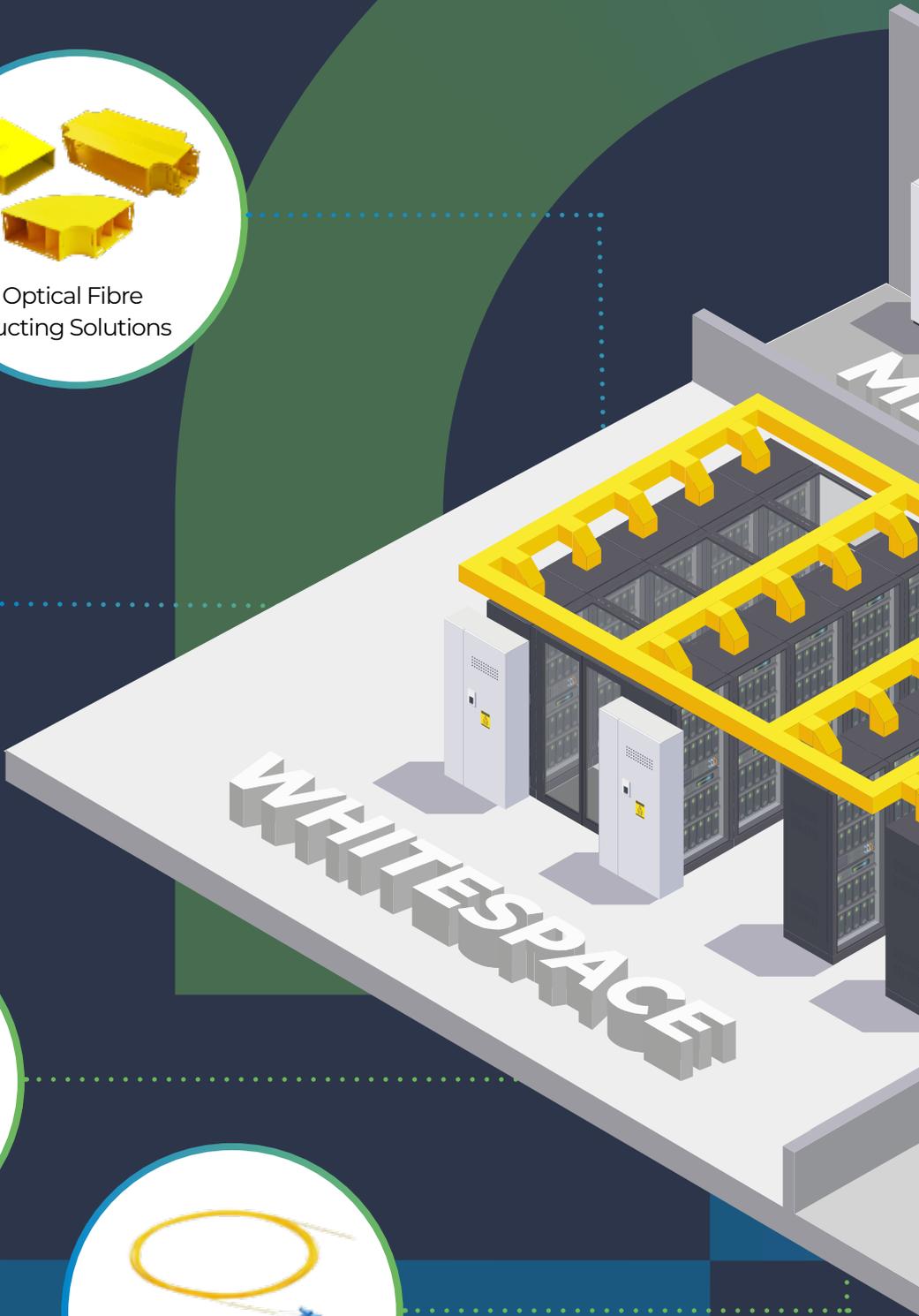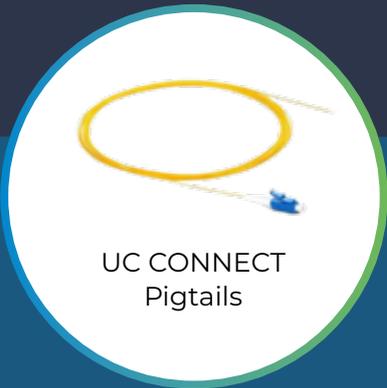




Ultra High-Density System



310 Series ODF

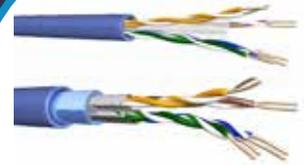

UC DATA Copper Cable



Trunk / Harness Cable



UC CONNECT Patch Panel



# MEET-ME ROOM SOLUTIONS



## 310 Series ODF

- 5 184 LC port capacity
- 19 x 2U sub-rack capacity
- 36 x 1U sub-rack capacity
- Integrated internal yellow ducting
- Offset cable slack management (max 4.1m)



Product sheet




## Sub-Rack Systems

### Splice & Patch

- Up to 144f
- 4 x 36f swing out trays per 1U
- Side or rear cable entry



Product sheet

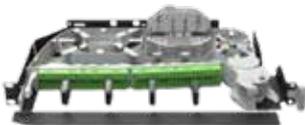

### Splice only or Patch Only

- 96f using 1.6mm patch cords
- 96f LC splice only



### Mass Fusion Splice

- up to:
  - 864f (FlexRibbon™)
  - 384f (stranded fibre in 1U)
- 2-Sided cable entry



## Fibre Management Accessories

### Fibre Optic Storage Tray

- Slide out for ease of access
- LH and RH access
- Pre-fitted cable saddles



Product sheet



### Cable Slack Management

- For both 600mm and 300mm ODF

# OPTICAL FIBRE DUCTING SOLUTIONS

Straight Duct



Breakouts



Reducers




Joiners



Express Outlets



Fibre Storage Loops

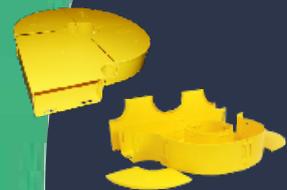

Tees, Elbows & Crosses



Drop-Off Solutions



Tubing




Product sheet



# WHITESPACE SOLUTIONS

## Trunk / Harness Cable

- Utilising all of our UC Future Cable portfolio
- Multiple fiber counts, designs up to 1728 core, with multiple MTP connector breakouts
- Base 8, 12, 16, 24 or 36 available
- Fully tested for low insertion loss and back reflection on every connector and attenuation loss
- Fully bespoke with short lead times
- 16f VSFF connector options available

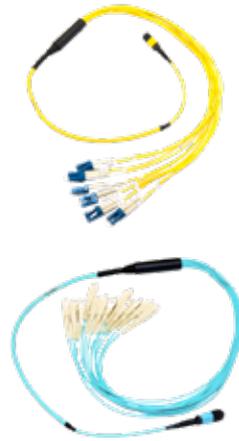

Product sheet

## Patch Cords

- Full fibre optic pigtail and patch cord portfolio available including LC, SC, ST in OM1-5 and G657.A1 & G657.A2
- European manufactured and CPR compliant patch cord range
- Simplex 1.6mm > 3.0mm up to B2<sub>ca</sub>
- Duplex in zipcord or flat-twin up to B2<sub>ca</sub>
- Duplex Uniboot in 2.0mm B2<sub>ca</sub>
- All manufactured using Prysmian produced fibre
- Full factory testing



Product sheet

## UC Connect Pigtails

- Utilising Prysmian 900µm easy stripping semi-tight buffered fibre
- Can be supplied with many different connector types such as FC, SC, ST, E2000, LC, DIN and others on request
- Available in OS2 and OM3-OM5
- UPC and APC available
- 100% optically tested



Product sheet

# WHITESPACE SOLUTIONS



## Patch Panel

- SystemLC, ST, SC
- Single & Multimode
- Colour-coded adapters
- 6-way up to 9 6-way
- Supplied with all required accessories – Splice Cassettes, Splice protectors, Glands, Warning Label, Earth Bonding Kit, Splice tray fibre identification label, Cage Nuts
- Built to order



Product sheet



## Multimedia System

- Available as LC-MPO, LC Splice or RJ4
- Up to 120 LC ports in 1U
- Available in OM3, OM4 & OM5 as well as G657.A1 & G657.A2
- Up to 20 RJ45 Ports using copper cassettes
- Compact size for installation inside shallow depth racks
- One click latch technology for easy installation
- Front module access



Product sheet




## Ultra High-Density System

- Ultra high-density fiber panels (144f LC)
- Tool-less technology Front and rear cassette loading
- Up to 12f per cassette Fully customisable sub-trays can accept base 8, 12 or 24
- Factory tested pre-terminated cassettes
- 1U, 2U and 4U Chassis



Product sheet

# COPPER SOLUTIONS

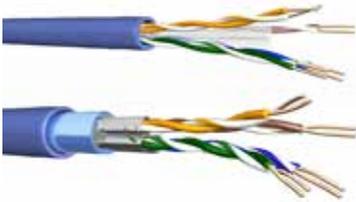

## UC DATA Copper Cable

- Cat. 6 to Cat. 8.2
- U/UTP, U/FTP, F/FTP, S/FTP
- Available in B2<sub>ca</sub>-s1a, d1, a1 / C<sub>ca</sub>-s1a, d1, a1 / D<sub>ca</sub>-s2, d2, a1 / E<sub>ca</sub> / F<sub>ca</sub> euroclass



Product sheet



## UC CONNECT Patch Panel

- Cat. 6 / Cat. 6A
- 19 inch rack mount
- Unshielded / Shielded
- Flat or angular, 24 and 28 ports



## Keystone Jack

- RJ45 Modular jack IDC Contact Cat. 6 and Cat. 6A
- Shielded and Unshielded version
- Tool Less version
- Field termination plug also available



## UC CONNECT Pre-Terminate Copper Trunk Cable

- RJ45-RJ45 Pre-Terminate Trunk Cable
- Cat. 6 / Cat. 6A U/UTP & F/FTP



## UC CONNECT Dual Boot & Slim flex Copper Patch Cord

- Cat. 6 and Cat. 6A stranded patch cord, LSZH
- Shielded 26AWG and Unshielded 24AWG
- 50µ gold plating contact

# CROSS CONNECT

## Medium Density (up to 432f LC)

- e.g. 6x 144F MTP/MPO trunk cables to bottom cluster of FTPs

- 72 x MTP/MPO12 trunk cables exit/enter from top RHS to customer equipment racks

IntelliFOX Blade



2 mm uniboot duplex patch cords routed between IntelliFOX blade and MTP-LC/A trays  
Left side access

IntelliFOX Blade



- 6 x 144F FTP's shown in top cluster = scalable to 864F (minimum proven capacity)

- MTP-LC transition cassettes 144F per RU  
This could potentially serve as a cross connect point and breakout to LC for these services  
- 36F horizontal cassettes x 4 per RU = 144F

- Patch cord routing and storage module

- Preterminated MTP/MPO-LC cabling

EQUIPMENT RACK

HypaFOX 1 RU tray with 4 x 36F LC cassettes or HypaFOX Z-Slim



Patch with LC duplex uniboot push/bull tab cords to equipment



Product sheet


## All the way up to Ultra High Density (5,184LC)

- LC duplex patch cords between ODF 1 & 2

- MTP/A 144F trunks Female - Female Polarity A. Haul sock one end

EQUIPMENT RACK


HypaFOX 1RU tray with 4x 36F LC cassettes

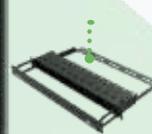

Patch with LC duplex uniboot push/bull tab cords to equipment



Product sheet

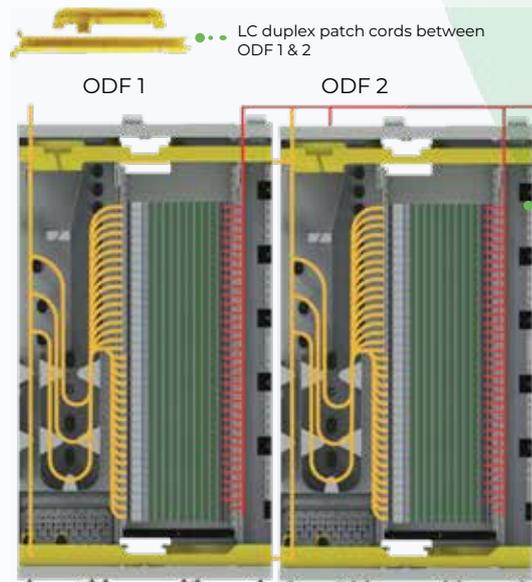

- MTP preterm trunk cables (12F, 24F, 36F or 144F, etc)  
Top right exit from ODF top

- IntelliFOX Blade
- 1 RU Modular Chassis with 4 x 36 FLC-A-MTP cassettes (144F)

- 36 x Scalable 1RU 144F FTP's (4 x 36F cassettes)

- Total port density of 5,184 LC/A fibres 144F per RU deployment



**Prysmian câbles et systèmes France**  
**Head office**

23 avenue Aristide Briand - BP 801 - PARON - 89108 SENS Cedex / France  
+33 (0)4 72 46 73 99 - [infocables.fr@prysmian.com](mailto:infocables.fr@prysmian.com)



© PRYSMIAN 2025 - PL406EN- V1 - November 2025 - All Rights Reserved. The information contained within this document must not be copied, reprinted or reproduced in any form, either wholly or in part, without the written consent of Prysmian. The information is believed correct at the time of issue. Prysmian reserves the right to amend this specification without notice. This specification is not contractually valid unless specifically authorised by Prysmian.